

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940522](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 3", Cable Diameter 4.57-6.35mm (.180-.250"), Approximate Break Strength 136.08kg (300 lbs)

**Documents:**


[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Literature Order No	987650-8066
Product Name	Fiber Optic
Type	Support Grip
UPC	78678836670
Woodhead	Yes
<b>Physical</b>	
Approximate Break Strength	136.08kg (300 lbs)
Bale Length	0.076m (3.00")
Body Style	Straight
Cable Diameter	4.57-6.35mm (.180-.250")
Color - Grommet	N/A
Gender	N/A
Material - Body	Aluminum
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.043m (1.70")
Number of Holes	N/A
Thread Size	N/A
<b>Material Info</b>	
Engineering Number	36670
<b>Reference - Drawing Numbers</b>	
Sales Drawing	SD-130094-001

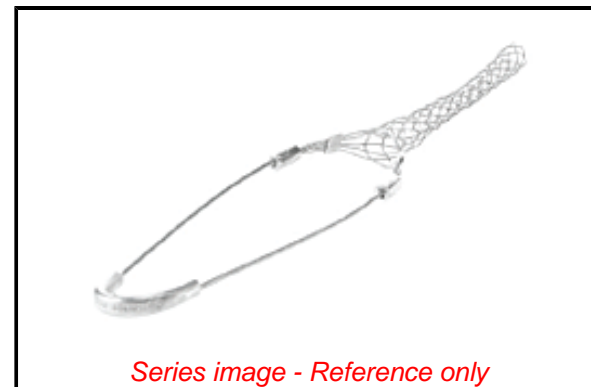

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

**Search Parts in this Series**

[130094 Series](#)