

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130097-0262](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** Dust-Tight Strain Relief Wide Range Grip, 3/4" NPT, Straight Male, Cable Diameter 13.21-18.54mm (.520-.730"), Approximate Break Strength 204.12kg (450 lbs)

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159  
 UL E76954

**General**

Product Family Cable Grips  
 Series [130097](#)  
 Eye Type N/A  
 Insulated Yes  
 NEMA Rating Dust Tight  
 O-Ring N/A  
 Overview [Strain-Relief Cord Grips](#)  
 Product Literature Order No 987650-8064  
 Product Name Dust-Tight  
 Type Strain Relief Grip  
 UPC 78678836508  
 Use With 3/4" NPT MAX-LOC® Lock Nut [130099-0144](#) , 3/4" NPT MAX-LOC® Gasket Sealing Ring [130099-0150](#) , 3/4" NPT MAX-LOC® O-Ring [130180-0333](#)  
 Woodhead Yes

**Physical**


Approximate Break Strength 204.12kg (450 lbs)  
 Bale Length N/A  
 Body Style Straight  
 Cable Diameter 13.21-18.54mm (.520-.730")  
 Color - Grommet N/A  
 Gender Male  
 Material - Body Zinc Plated Steel  
 Material - Grip Galvanized Steel  
 Mesh Length 0.19m (7.50")  
 Number of Holes N/A  
 Thread Size 3/4" NPT

**Material Info**

Old Part Number 36508

**Reference - Drawing Numbers**

Sales Drawing SD-130097-002

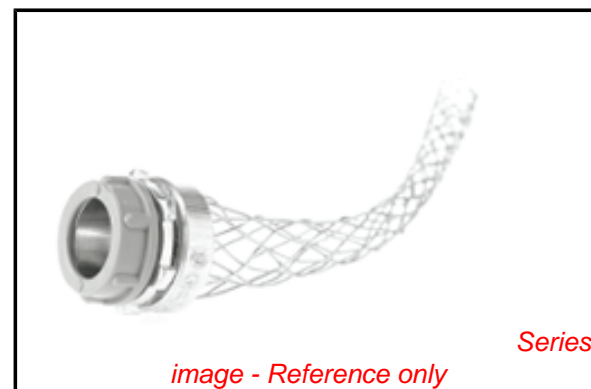

**EU RoHS**

**ELV and RoHS Compliant**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

Not Reviewed

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

130097Series