

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300250408](#)
Status: **Active**
Overview: [Brad® Mini-Change® Connectors](#)
Description: Mini-Change Double-Ended Cordset, 5 Poles, Female (Straight) to Male (Straight), 15/18 AWG, DeviceNet Thick Flex-Rated Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
Series [130025](#)
Connector End A Mini-Change
Connector End B Mini-Change
IP Rating IP67
Material - Contact Brass
Overview [Brad® Mini-Change® Connectors](#)
Product Name DeviceNet* Trunk, Mini-Change®
Region Europe
Type Double Ended
UPC 78678846493

Physical

Cable Diameter 12.10mm (.480")
Cable Length 1.0m (3.28')
Color - Cable Jacket Gray
Coupling Style Threaded
Gender Female-Male
Keyway Single
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Coupling Nut Die-Cast Zinc
Material - Plating Mating Gold
Orientation Straight to Straight
Poles 5
Temperature Range - Operating -20°C to +80°C
Wire Size AWG 15, 18
Wire/Cable Type N/A

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DNF11A-M010

Reference - Drawing Numbers

Sales Drawing SD-130025-015

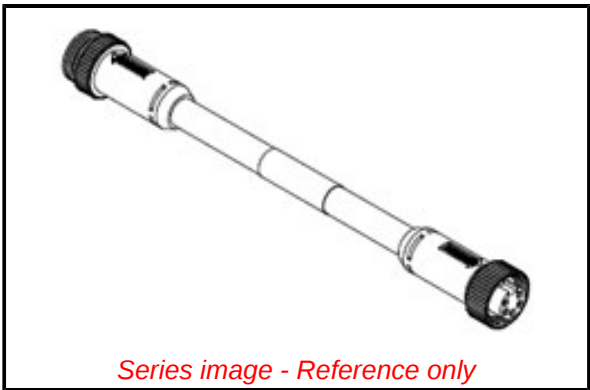

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130025](#) Series