

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300250352](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Micro-Change (M12) Double-Ended Cordset, 5 Poles, Male (Straight) to Female (Straight) , 22 AWG, DeviceNet Thin High Flex Stranded Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130025](#)
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name DeviceNet* Trunk, Mini-Change®
 Region Europe
 Type Double Ended
 UPC 78678851663

Physical

Cable Diameter N/A
 Cable Length 1.0m (3.28')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket TPE
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Nickel
 Orientation Straight to Straight
 Poles 5
 Temperature Range - Operating -20°C to +75°C
 Wire Size AWG 22
 Wire/Cable Type N/A

Electrical


Current - Maximum per Contact 8.0A
 Voltage - Maximum 600V AC/DC

Material Info

Engineering Number DNE11A-M010

Reference - Drawing Numbers

Sales Drawing SD130025-027

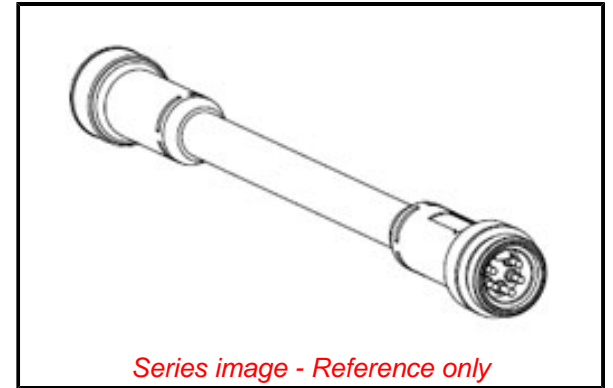

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130025 Series](#)