

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300240032](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change Single-Ended Cordset, 5 Poles, Male (Straight) to DeviceNet Thick (Trunk) Pigtail Cable, 15 and 18 AWG, 3.0m (9.84') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130024](#)
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name DeviceNet* Trunk, Mini-Change®
 Region Europe
 Type Single Ended
 UPC 78678801150

Physical

Cable Diameter 12.10mm (.480")
 Cable Length 3.0m (9.84')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Male-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Die-Cast Zinc
 Material - Plating Mating Gold
 Orientation Straight to Pigtail
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 15, 18
 Wire/Cable Type Thick (Trunk)

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DN01A-M030

Reference - Drawing Numbers

Sales Drawing SD-130024-001

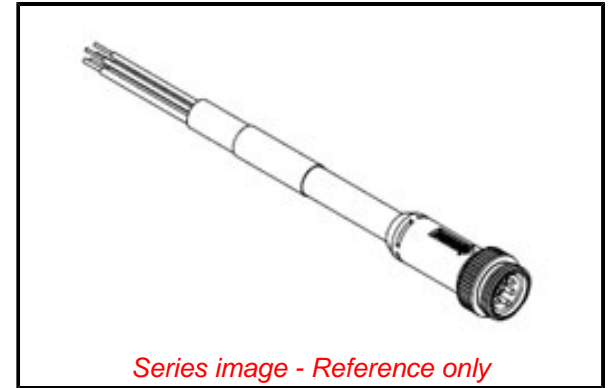

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

Search Parts in this Series

[130024 Series](#)