

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300630150**
Status: **Active**
Overview: Brad® Quick-Change® Connectors
Description: Quick-Change Single-Ended Cordset, 4 Poles, Male (Straight) to Pigtail, 10 AWG, PVC Cable, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Cordsets
 Series 130063
 Connector End A Quick-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview Brad® Quick-Change® Connectors
 Product Name Quick-Change®
 Protocol EtherNet
 Region Europe
 Type Single Ended
 UPC 78678862180

Physical

Cable Diameter 19.81mm (.780")
 Cable Length 2.0m (6.56')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Male-Pigtail
 Keyway Single
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Anodized Aluminum
 Material - Plating Mating Gold over Nickel
 Orientation Straight to Pigtail
 Poles 4
 Temperature Range - Operating -20°C to +90°C
 Wire Size AWG 10
 Wire/Cable Type ST00W, TC-ER Direct Burial

Electrical


Current - Maximum per Contact 25.0A
 Voltage - Maximum 600V AC/DC

Material Info

Engineering Number C04006A48M020

Reference - Drawing Numbers

Sales Drawing SD-130063-042

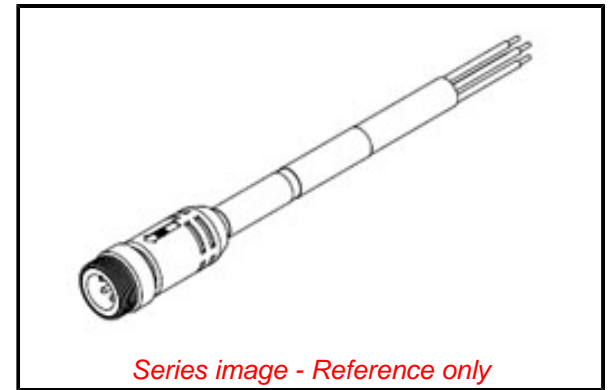

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130063 Series