

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300100795**
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change A-Size Double-Ended Cordset, 4 Poles, Male (Straight) to Female (Straight), 16 AWG, PVC Cable, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series 130010
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview Brad® Mini-Change® Connectors
 Product Name Mini-Change®
 Protocol DeviceNet
 Region America
 Type Double Ended
 UPC 78678838237

Physical

Cable Diameter 10.67mm (.420")
 Cable Length 2.0m (6.56')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Nickel
 Orientation Straight to Straight
 Poles 4
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 10.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 114030A38M020

Reference - Drawing Numbers

Sales Drawing SD-130010-013

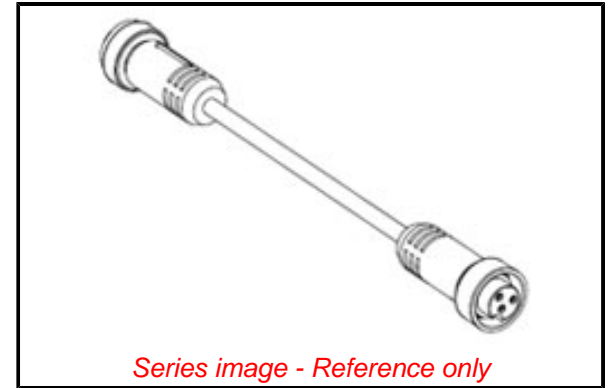

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130010 Series](#)