

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201190026](#)
Status: **Active**
Overview: Brad® Ultra-Lock® Connection System
Description: Ultra-Lock (M12) Molded Junction Box with Molded Cable, 8 Port, PNP, 10.0m Cable Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Passive Distribution Boxes
Series	120119
IP Rating	IP68
NEMA Rating	NEMA 6
Overview	Brad® Ultra-Lock® Connection System
Product Name	Ultra-Lock® (M12) Dist Boxes
UPC	78678899580

Physical

Bus I/O	Ultra-Lock (M12)
Cable Connector Orientation	Straight
Cable Length	10.0m
Home Run Cable Length	N/A
Home Run Connector	N/A
Home Run Interface	N/A
Keyway	Single
LED Indicator	Yes
Material - Cable Jacket	PUR
Material - Housing	PBT
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Nickel
Orientation	Side Mount
Poles	5
Poles (wired)	4
Ports	8
Temperature Range - Operating	-25°C to +90°C
Wiring Configuration	Single I/O per Port

Electrical


Current - Maximum per Contact	12.0A per module, 4.0A per port
Functional Wiring	PNP
Voltage - Maximum	10-30V DC

Material Info

Engineering Number	BKY800P-FBP-10
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-120119-009
---------------	---------------

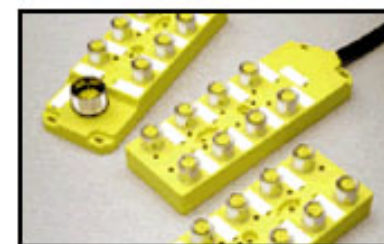

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[120119 Series](#)