

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

120072-0250

Status:

Active

Overview:

Brad® Micro-Change® (M12) Connectors

Description:

Micro-Change® (1/2"-20 UNF) Single-Ended Cordset, 3 Poles, Female (90°) to Pigtail, 22 AWG, PVC Cable, 1.83m (6.0') Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR6837

UL

E152210

General

Product Family

Industrial Cordsets

Series

120072

Connector End A

Micro-Change® (1/2" - 20 UNF)

Connector End B

Pigtail

IP Rating

IP67

Overview

Brad® Micro-Change® (M12) Connectors

Product Name

Micro-Change® (1/2" - 20 UNF)

Protocol

N/A

Region

America

Type

Single Ended

UPC

78678875912

Physical

Cable Diameter

5.72mm (.225")

Cable Length

1.83m (6.0')

Color - Cable Jacket

Yellow

Coupling Style

Threaded

Gender

Female-Pigtail

Keyway

Dual

LED Indicator

No

Material - Cable Jacket

PVC

Material - Connector Body

PVC

Material - Contact

Copper Alloy

Material - Coupling Nut

Black Epoxy Coated Zinc

Material - O-Ring

Nitrile Rubber

Material - Plating Mating

Gold over Nickel

Net Weight

244.390/g

Orientation

90° to Straight

Poles

3

Temperature Range - Operating

-20°C to +105°C

Wire Size AWG

22

Wire/Cable Type

UL 2661

Electrical

Current - Maximum per Contact

4A

Voltage - Maximum

250V AC/DC

Material Info


Old Part Number

703001D02F060

Reference - Drawing Numbers

Sales Drawing

SD-120072-010

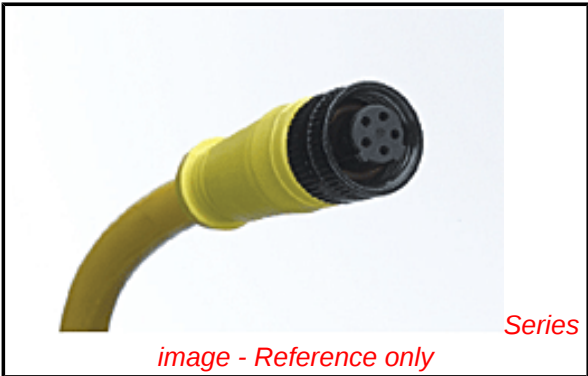

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

120072Series

This document was generated on 10/10/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION