

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300080350](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change C-Size Single-Ended Cordset, 9 Poles, Female (90°) to Pigtail, 16 AWG, PVC Cable, 0.91m (3.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130008](#)
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name Mini-Change®
 Protocol DeviceNet
 Region America
 Type Single Ended
 UPC 78678844135

Physical

Cable Diameter 16.26mm (.640")
 Cable Length 0.91m (3.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Orientation 90° to Pigtail
 Poles 9
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 7.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 309001A01F030

Reference - Drawing Numbers

Sales Drawing SD-130008-015

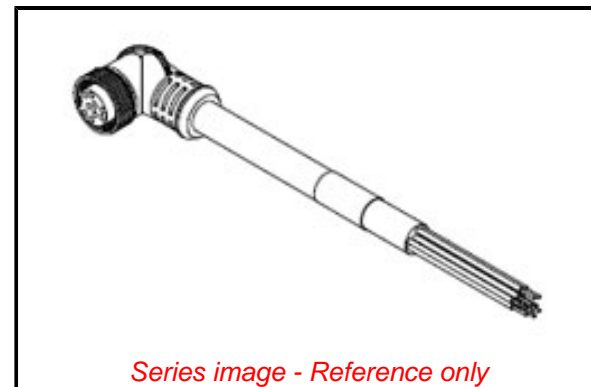

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130008 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION