

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300250412](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change Double-Ended Cordset, 5 Poles, Female (Straight) to Male (Straight), 15/18 AWG, DeviceNet Thick Flex-Rated Cable, 3.0m (9.84') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130025](#)
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name DeviceNet* Trunk, Mini-Change®
 Region Europe
 Type Double Ended
 UPC 78678849032

Physical

Cable Diameter 12.10mm (.480")
 Cable Length 3.0m (9.84')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Die-Cast Zinc
 Material - Plating Mating Gold
 Orientation Straight to Straight
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 15, 18
 Wire/Cable Type Thick Flex-Rated Cable

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DNF11A-M030

Reference - Drawing Numbers

Sales Drawing SD-130025-015

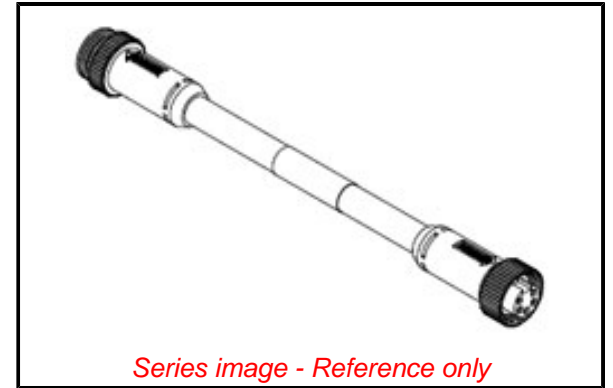

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130025 Series](#)