


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1120115027](#)
Status: **Active**
Overview: [PC Network Interface Cards](#)
Description: applicom PCIE1500S7 Card, PROFIBUS (S7/MPI), 1 Channel, PCI Express 1x - OPC/DLL/DAS - SCADA/HMI

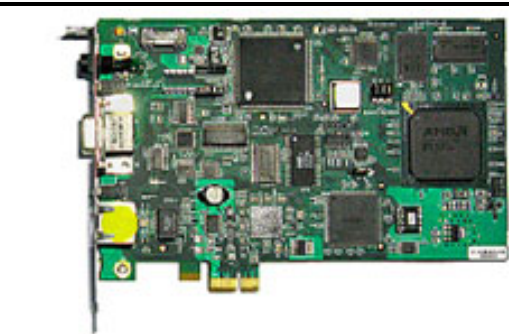

Series image - Reference only

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

General	
Product Family	Network Interface
Series	112011
Application	HMI, SCADA
Approvals	CE certified
Communication Speed	PROFIBUS 9.6 kbps to 1.5 Mbps
Mounting Style	PC Slot
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista
Overview	PC Network Interface Cards
Product Literature Order No	987651-3769
Product Name	applicom
Protocol	PROFIBUS
Protocol Detail	PROFIBUS FDL Send/Receive, PROFIBUS MPI Master, PROFIBUS S7 Client
Slot	PCI Express 1x
Software Downloads	APP-PS7-PCIE
Type	PROFIBUS Card
UPC	883906487737
Woodhead	Yes
Physical	
Channels	1
Interface	DAServer, DDE Server, DLL, OPC DA
Net Weight	140.000/kg
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Packaging Type	Carton
Processor	AMD SC520
Temperature Range - Operating	0°C to +65°C
Electrical	
Current - Maximum Input	5.5W
EMC	EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	3.3V
Material Info	
Engineering Number	APP-PS7-PCIE

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[112011](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION