

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1120185005](#)  
**Status:** **Active**  
**Overview:** PC Network Interface Cards  
**Description:** Direct-Link CPCI-DPIO Card, PROFIBUS-DP Master/Slave, 1 Channel, CompactPCI - OPC/DLL/LIB/DAS - Control

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

**General**

Product Family	Network Interface
Series	<a href="#">112018</a>
Application	IO Control
Approvals	CE certified
Exclude SD Check	Yes
Overview	<a href="#">PC Network Interface Cards</a>
Product Literature Order No	987650-5288
Product Name	applicom IO
Protocol	PROFIBUS
Protocol Detail	PROFIBUS DPV0 Master, PROFIBUS DPV0 Slave, PROFIBUS DPV1 Master
Software Downloads	DRL-DPM-CPI
Type	PROFIBUS Card
UPC	887191524184

**Physical**


Channels	1
Communication Speed	PROFIBUS 9.6 kbps to 12 Mbps
Interface	DLL, OPC DA
Mounting Style	PC Slot
Net Weight	150.000/g
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista, WindowsXP
Packaging Type	Carton
Processor	AMD SC520
Slot	Compact PCI 5V
Temperature Range - Operating	0°C to +65°C

**Electrical**

Current - Maximum Input	5.5W
EMC	EN 55022 Class B, EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	5V

**Material Info**

Engineering Number	DR2-DPM-CPU
--------------------	-------------

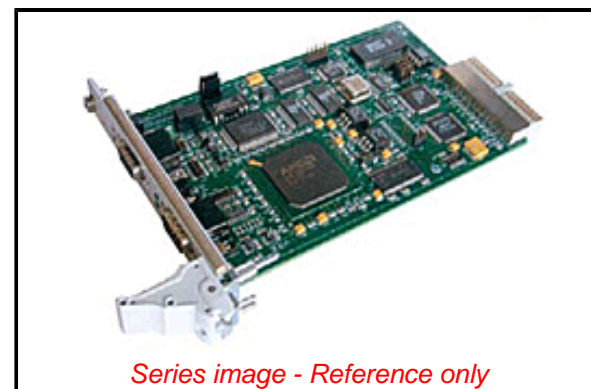

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[112018 Series](#)