

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1210120175](#)  
**Status:** **Active**  
**Overview:** mPm DIN Valve Connectors  
**Description:** mPm DIN Base, Form A-18mm, B26 Base, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Gasket with Screw, UL94-V0 Rated

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E218123

**General**

Product Family Field Attachable / Accessories  
 Series [121012](#)  
 Form A - 18mm  
 IP Rating IP65, IP67  
 Material - Contact Brass  
 Overview [mPm DIN Valve Connectors](#)  
 Product Name mPm  
 Type Field Attachable Connector  
 UPC 78172537161

**Physical**


Cable Diameter N/A  
 Coupling Type N/A  
 Diagnostics / LEDs No  
 Diagnostics Port No  
 Gender N/A  
 Keyway None  
 Material - Connector Body Polypropylene  
 Material - Coupling Nut N/A  
 Material - Plating Mating Silver  
 Net Weight 12.000/g  
 Orientation Straight  
 Pitch - Mating Interface 18.00mm  
 Poles 3  
 Temperature Range - Operating -40°C to +125°C  
 Wire Size AWG N/A

**Electrical**

Current - Maximum per Contact 16.0A  
 Voltage - Maximum 250V AC / 300V DC

**Material Info**

Engineering Number B263000W2SA

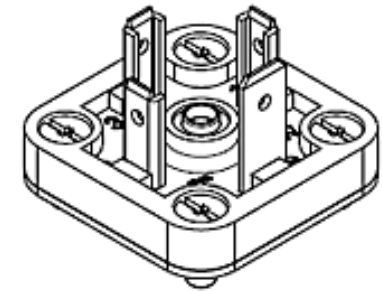

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Not Contained Per - D(2020)4578-DC (25 June 2020)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[121012 Series](#)