



FEMALE PLUG M12 90° ANGLED TO MALE PLUG M12 STRAIGHT

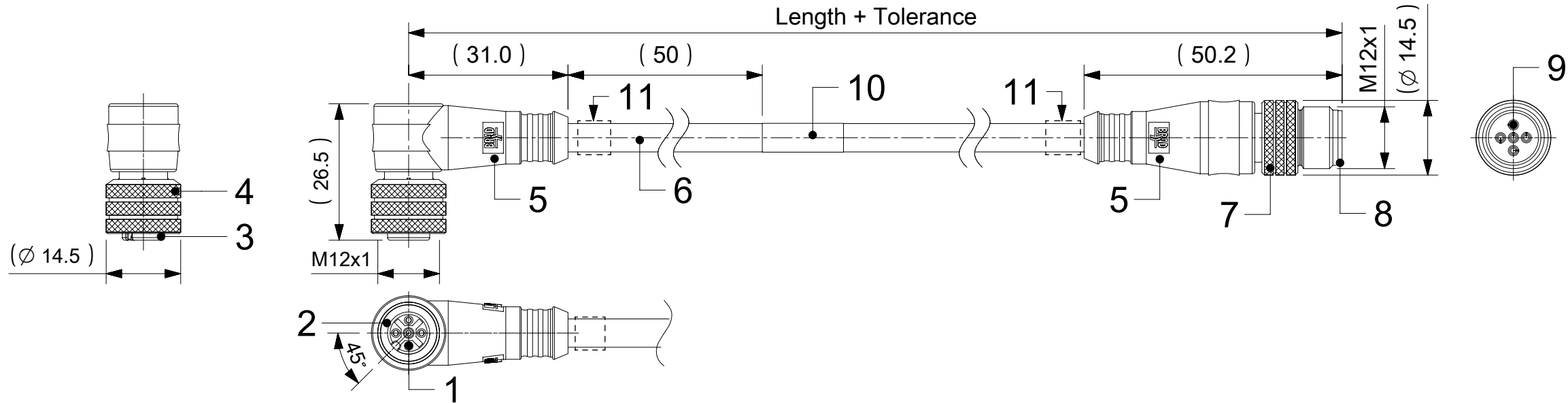

NOTES:

RATED VOLTAGE: 3, 4 contacts 250V per IEC 60664
5 contacts 60V per IEC 60664
5 contacts 250V per UL 2238
8 contacts 30V per IEC 60664
RATED CURRENT: 3, 4, 5 contacts 4A
8 contacts 2A
PROTECTION CLASS: IP 67
TEMPERATURE: -25°C / +85°C

* FOR CABLES lxx USE PRINTING ON THE CABLE IN THE SAME MEASUREMENT LIKE FOR LABEL – ENGINEERING No

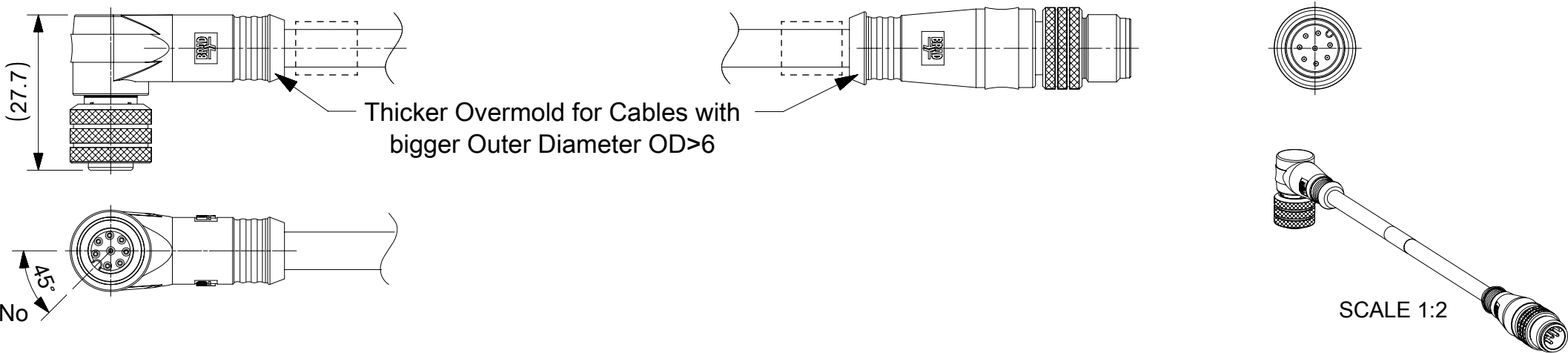

CONTACTS POSITION FRONT VIEW:

	3 CONTACTS		4 CONTACTS		5 CONTACTS		8 CONTACTS	
FEMALE								
MALE								
CONNECTIONS	PIN	WIRE	PIN	WIRE	PIN	WIRE	PIN	WIRE
	1	BROWN	1	BROWN	1	BROWN	1	WHITE
	2	---	2	WHITE	2	WHITE	2	BROWN
	3	BLUE	3	BLUE	3	BLUE	3	GREEN
	4	BLACK	4	BLACK	4	BLACK	4	YELLOW
	5	---	5	---	5	GREY OR GREEN/YELLOW	5	GREY
							6	PINK
							7	BLUE
CODING REQUIRED TO IEC 61076-2-101								

FOR OPTIONS SEE - NUMERICAL CODE - ON SHEET 2

11	SEE PART LIST	ID CARRIER	PVC	TRANSPARENT
10	1	LABEL YELLOW	VINYL	---
	-	PRINTING FOR CABLES lxx	---	---
9	3 / 4 / 5 / 8	CONTACT MALE	SEE PART LIST	SELECTIVE Au OVER Ni
8	1	INSERT MALE BLACK	SEE PART LIST	---
7	1	COUPLING NUT MALE	SEE PART LIST	---
6	-	CABLE	SEE SHEET 2	---
5	-	OVERMOULDING BLACK	SEE PART LIST	---
4	1	COUPLING NUT FEMALE	SEE PART LIST	---
3	1	INSERT FEMALE BLACK	SEE PART LIST	---
2	1	O-RING RED	FPM	---
1	3 / 4 / 5 / 8	CONTACT FEMALE	SEE PART LIST	SELECTIVE Au OVER Ni
ITEM	QTY.	DESCRIPTION	MATERIAL	FINISH

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION		CURRENT REV DESC: REMOVED OBSOLETE PART NUMBER AS PER PCN#517152		
DIMENSION UNITS	SCALE			
mm	1:1			
GENERAL TOLERANCES (UNLESS SPECIFIED)		CSE M12 XP AC FE RA MA STR XM DE		
ANGULAR TOL	± 1.0 °	PRODUCT CUSTOMER DRAWING		
4 PLACES	±	EC NO: 840847	2025/11/21	
3 PLACES	±	DRWN: PONNAM	2025/11/25	
2 PLACES	± 0.05	CHK'D: GGA	2025/11/25	
1 PLACE	± 0.3	APPR: GGA	INITIAL REVISION:	
0 PLACES	± 0.5	DRWN: JMARSZALEK	2016/10/06	
DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		APPR: RSILLER	2016/12/08	
THIRD ANGLE PROJECTION		DRAWING	SERIES	DOCUMENT NUMBER
		A3-SIZE	120066	1200660973
MATERIAL NUMBER		CUSTOMER		DOC TYPE
		GENERAL MARKET		PSD
SHEET NUMBER		1 OF 4		DOC PART
				000
				A12

ENGINEERING NO. - NUMERICAL CODE

(Available parts see PART LIST table. Other parts available upon request).

OPTIONS

8

8

X

0

X

1

X

X

X

X

X

X

X

X

88=Micro-Change
M12x1
Double ended

Contacts:
3=3 Contacts
4=4 Contacts
5=5 Contacts
8=8 Contacts

Heads style:
031=Plug Female 90°
to Plug Male Straight
021=Plug Female 90°
to Plug Male Straight
with Female
Coupling Nut

Cable type: See Table

Units:
M=Meter
C=Centimeter


Length
Examples:
005=0.5 unit
010=1 unit
100=10 units

Overmold color:
Blank (Standard)=Black TPU
Blank=Yellow TPU for cables
A09, S19, S20, S26
Blank=Yellow TPE-E for cables
K03, K05
A=Grey / G=Black / Y=Yellow

Coupling Nut:
Blank (Standard)=Knurled Brass Ni Plated
1=Hexagonal Stainless steel
5=Knurled Derlin
7=Knurled Brass Ni Plated, Teflon Coated
Blank=7 for cables I20, I26, K03, K05, P82, S26
9=Knurled / Hexagonal Brass Ni Plated SW13

H= 2 pcs. of I/D Carrier PVC Transparent
(Cables Ixx & P82 always with 2 pcs. of
I/D Carrier even if no H in Engineering No.)

COUPLING NUT
FEMALE MALE

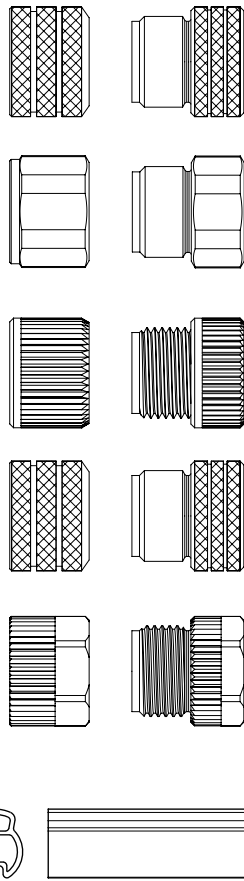

CABLE INFORMATION

(for more information see Cable Data Sheet).

CABLE TYPE	NO. OF WIRES	CROSS SECTION	CABLE JACKET	UL	CSA	STATIC: TEMP. / BENDING RADIUS	DYNAMIC: TEMP. / BENDING RADIUS	DRAG CHAIN	SHIELD
I03	3 / 4 / 5	0.34mm²	PVC CEI GREY	-	-	-30°C to +70°C	-5°C to +70°C	-	-
I20	3 / 4	0.34mm²	PVC CEI GREY	-	-	-30°C to +70°C	-5°C to +70°C	-	YES
I26	5	0.34mm²	PVC CEI GREY	-	-	-30°C to +70°C	-5°C to +70°C	-	YES
K03	4	18AWG	TPE YELLOW	UL ITC or PLC	I/II A/B 90°C/300V	max 105°C	-	-	-
K05	3 / 4 / 5	22AWG	TPE YELLOW	UL ITC or PLC	I/II A/B 90°C/300V	max 105°C	-	-	-
P82	3 / 4 / 5	0.34mm²	PUR IRR ORANGE	-	-	-50°C to +105°C, >5xO.D.	-40°C to +105°C, >7.5xO.D.	-	-
S20	3 / 4 / 5	0.34mm²	PVC YELLOW	UL 2661/1731	C22.2 II A 105°C/300V	-30°C to +105°C	-	-	YES
E02	3 / 4 / 5 / 8	0.25mm²	PVC BLACK	UL 2464/1729	C22.2 I/II A/B 80°C/300V	-30°C to +80°C, 10xO.D.	-10°C to +80°C, 15xO.D.	-	-
E03	3 / 4 / 5	0.34mm²	PVC BLACK	UL 2464/1729	C22.2 I/II A/B 80°C/300V	-30°C to +80°C, 10xO.D.	-10°C to +80°C, 15xO.D.	-	-
H09	3 / 4 / 5	0.34mm²	PUR BLACK LSOH	UL 21198/10493	C22.2 I/II A/B 80°C/300V	-40°C to +80°C, 5xO.D.	-25°C to +80°C, 10xO.D.	2 000 000 cycles at 20°C, Temp. range +5°C to +60°C	-
P03	3 / 4 / 5	0.34mm²	PUR / PVC BLACK	-	-	-30°C to +80°C, >7xO.D.	-5°C to +80°C, >15xO.D.	-	-
H08	8	0.25mm²	PUR BLACK LSOH	UL 21198/10493	UL 21198/10493	-40°C to +80°C, >5xO.D.	-25°C to +80°C, >10xO.D.	2 000 000 cycles, Temp max 60°C	-
P02	8	0.25mm²	PUR / PVC BLACK	-	-	-30°C to +80°C, >7xO.D.	-5°C to +80°C, >15xO.D.	-	-

CABLE LENGTH TOLERANCES

OVER	UP TO AND INCLUDING	TOLERANCES
0	305mm	+19mm
305mm	915mm	+45mm
915mm	1830mm	+56mm
1830mm	3660mm	+89mm
3660mm	7320mm	+165mm
7320mm	14640mm	+317mm
14640mm	30500mm	+610mm
30500mm	>	+2% of finished length

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION

DIMENSION UNITS

mm

SCALE

1:1

GENERAL TOLERANCES (UNLESS SPECIFIED)

ANGULAR TOL ± 1.0 °

4 PLACES ±

3 PLACES ±

2 PLACES ± 0.05

1 PLACE ± 0.3

0 PLACES ± 0.5

DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS

CURRENT REV DESC: REMOVED OBSOLETE PART NUMBER AS PER PCN#517152

EC NO: 840847

DRWN: PONNAM

CHK'D: GGA

APPR: GGA

INITIAL REVISION:

DRWN: JMARSZALEK

APPR: RSILLER

THIRD ANGLE PROJECTION

DRAWING

SERIES

MATERIAL NUMBER

CUSTOMER

SHEET NUMBER

2025/11/21

2025/11/25

2025/11/25

2016/10/06

2016/12/08

A3-SIZE

120066

GENERAL MARKET

2 OF 4

mo

lex

CSE M12 XP AC FE RA MA STR XM DE

PRODUCT CUSTOMER DRAWING

DOCUMENT NUMBER

1200660973

DOC TYPE

PSD

DOC PART

000

REVISION

A12

	10	9	8	7	6	5	4	3	2	1																																																																																																																																																																			
	PART LIST																																																																																																																																																																												
F	<table> <tr><th>No.</th><th>Part No.</th><th>Engineering No.</th><th>Cable Length</th></tr> <tr><td>1</td><td>1200060052</td><td>884031I20M005</td><td>0.5m</td></tr> <tr><td>2</td><td>1200060053</td><td>884031I20M010</td><td>1m</td></tr> <tr><td>3</td><td>1200060054</td><td>884031I20M015</td><td>1.5m</td></tr> <tr><td>4</td><td>1200060055</td><td>884031I20M020</td><td>2m</td></tr> </table>				No.	Part No.	Engineering No.	Cable Length	1	1200060052	884031I20M005	0.5m	2	1200060053	884031I20M010	1m	3	1200060054	884031I20M015	1.5m	4	1200060055	884031I20M020	2m	<table> <tr><th>No.</th><th>Part No.</th><th>Engineering No.</th><th>Cable Length</th></tr> <tr><td>36</td><td>1200072725</td><td>885031I26M005</td><td>0.5m</td></tr> <tr><td>37</td><td>1200072726</td><td>885031I26M010</td><td>1m</td></tr> <tr><td>38</td><td>1200659070</td><td>884031I20M010Y</td><td>1m</td></tr> <tr><td>39</td><td>1200659071</td><td>884031I20M015Y</td><td>1.5m</td></tr> </table>				No.	Part No.	Engineering No.	Cable Length	36	1200072725	885031I26M005	0.5m	37	1200072726	885031I26M010	1m	38	1200659070	884031I20M010Y	1m	39	1200659071	884031I20M015Y	1.5m	<table> <tr><th>No.</th><th>Part No.</th><th>Engineering No.</th><th>Cable Length</th></tr> <tr><td>71</td><td>1200665039</td><td>884031S20M003</td><td>0.3m</td></tr> <tr><td>72</td><td>1200665053</td><td>884031S20M060H</td><td>6m</td></tr> <tr><td>73</td><td>1200665074</td><td>884031K05M080</td><td>8m</td></tr> <tr><td>74</td><td>1200668052</td><td>883031S20M006</td><td>0.6m</td></tr> </table>				No.	Part No.	Engineering No.	Cable Length	71	1200665039	884031S20M003	0.3m	72	1200665053	884031S20M060H	6m	73	1200665074	884031K05M080	8m	74	1200668052	883031S20M006	0.6m	<table> <tr><th>Pos.</th><th>Part No.</th><th>Engineering No.</th><th>Cable Length</th></tr> <tr><td>106</td><td>1200668912</td><td>883031E03M050H</td><td>5m</td></tr> <tr><td>107</td><td>1200668175</td><td>883031E03M060</td><td>6m</td></tr> <tr><td>108</td><td>1200070127</td><td>883031E03M100</td><td>10m</td></tr> <tr><td>109</td><td>1200658762</td><td>883031H09M006</td><td>0.6m</td></tr> </table>				Pos.	Part No.	Engineering No.	Cable Length	106	1200668912	883031E03M050H	5m	107	1200668175	883031E03M060	6m	108	1200070127	883031E03M100	10m	109	1200658762	883031H09M006	0.6m	F																																																																												
No.	Part No.	Engineering No.	Cable Length																																																																																																																																																																										
1	1200060052	884031I20M005	0.5m																																																																																																																																																																										
2	1200060053	884031I20M010	1m																																																																																																																																																																										
3	1200060054	884031I20M015	1.5m																																																																																																																																																																										
4	1200060055	884031I20M020	2m																																																																																																																																																																										
No.	Part No.	Engineering No.	Cable Length																																																																																																																																																																										
36	1200072725	885031I26M005	0.5m																																																																																																																																																																										
37	1200072726	885031I26M010	1m																																																																																																																																																																										
38	1200659070	884031I20M010Y	1m																																																																																																																																																																										
39	1200659071	884031I20M015Y	1.5m																																																																																																																																																																										
No.	Part No.	Engineering No.	Cable Length																																																																																																																																																																										
71	1200665039	884031S20M003	0.3m																																																																																																																																																																										
72	1200665053	884031S20M060H	6m																																																																																																																																																																										
73	1200665074	884031K05M080	8m																																																																																																																																																																										
74	1200668052	883031S20M006	0.6m																																																																																																																																																																										
Pos.	Part No.	Engineering No.	Cable Length																																																																																																																																																																										
106	1200668912	883031E03M050H	5m																																																																																																																																																																										
107	1200668175	883031E03M060	6m																																																																																																																																																																										
108	1200070127	883031E03M100	10m																																																																																																																																																																										
109	1200658762	883031H09M006	0.6m																																																																																																																																																																										
E	<table> <tr><td>5</td><td>1200070132</td><td>883031I03M003</td><td>0.3m</td></tr> <tr><td>6</td><td>1200070133</td><td>883031I03M006</td><td>0.6m</td></tr> <tr><td>7</td><td>1200070134</td><td>883031I03M010</td><td>1m</td></tr> <tr><td>8</td><td>1200070136</td><td>883031I03M020</td><td>2m</td></tr> <tr><td>9</td><td>1200070137</td><td>883031I03M030</td><td>3m</td></tr> <tr><td>10</td><td>1200070138</td><td>883031I03M050</td><td>5m</td></tr> <tr><td>11</td><td>1200070152</td><td>883031S20M010</td><td>1m</td></tr> <tr><td>12</td><td>1200070153</td><td>883031S20M020</td><td>2m</td></tr> <tr><td>13</td><td>1200070156</td><td>883031S20M050</td><td>5m</td></tr> </table>				5	1200070132	883031I03M003	0.3m	6	1200070133	883031I03M006	0.6m	7	1200070134	883031I03M010	1m	8	1200070136	883031I03M020	2m	9	1200070137	883031I03M030	3m	10	1200070138	883031I03M050	5m	11	1200070152	883031S20M010	1m	12	1200070153	883031S20M020	2m	13	1200070156	883031S20M050	5m	<table> <tr><td>40</td><td>1200659115</td><td>884031I20M005Y</td><td>0.5m</td></tr> <tr><td>41</td><td>1200660374</td><td>884031K05M005</td><td>0.5m</td></tr> <tr><td>42</td><td>1200660375</td><td>884031K05M006</td><td>0.6m</td></tr> <tr><td>43</td><td>1200660376</td><td>884031K05M010</td><td>1m</td></tr> <tr><td>44</td><td>1200660377</td><td>884031K05M015</td><td>1.5m</td></tr> <tr><td>45</td><td>1200660378</td><td>884031K05M020</td><td>2m</td></tr> <tr><td>46</td><td>1200660379</td><td>884031K05M030</td><td>3m</td></tr> <tr><td>47</td><td>1200660380</td><td>884031K05M040</td><td>4m</td></tr> <tr><td>48</td><td>1200660381</td><td>884031K05M050</td><td>5m</td></tr> <tr><td>49</td><td>1200660382</td><td>884031K05M060</td><td>6m</td></tr> </table>				40	1200659115	884031I20M005Y	0.5m	41	1200660374	884031K05M005	0.5m	42	1200660375	884031K05M006	0.6m	43	1200660376	884031K05M010	1m	44	1200660377	884031K05M015	1.5m	45	1200660378	884031K05M020	2m	46	1200660379	884031K05M030	3m	47	1200660380	884031K05M040	4m	48	1200660381	884031K05M050	5m	49	1200660382	884031K05M060	6m	<table> <tr><td>75</td><td>1200668071</td><td>884031S20M020</td><td>2m</td></tr> <tr><td>76</td><td>1200668191</td><td>883031S20M030</td><td>3m</td></tr> <tr><td>77</td><td>1200668237</td><td>883031S20M100</td><td>10m</td></tr> <tr><td>78</td><td>1200668258</td><td>883031I03M080</td><td>8m</td></tr> <tr><td>79</td><td>1200668287</td><td>884031I20M025</td><td>2.5m</td></tr> <tr><td>80</td><td>1200668667</td><td>884031I20M030Y</td><td>3m</td></tr> <tr><td>81</td><td>1200070443</td><td>884021S20M003</td><td>0.3m</td></tr> <tr><td>82</td><td>1200070444</td><td>884021S20M006</td><td>0.6m</td></tr> <tr><td>83</td><td>1200070445</td><td>884021S20M010</td><td>1m</td></tr> <tr><td>84</td><td>1200070446</td><td>884021S20M020</td><td>2m</td></tr> </table>				75	1200668071	884031S20M020	2m	76	1200668191	883031S20M030	3m	77	1200668237	883031S20M100	10m	78	1200668258	883031I03M080	8m	79	1200668287	884031I20M025	2.5m	80	1200668667	884031I20M030Y	3m	81	1200070443	884021S20M003	0.3m	82	1200070444	884021S20M006	0.6m	83	1200070445	884021S20M010	1m	84	1200070446	884021S20M020	2m	<table> <tr><td>110</td><td>1200658763</td><td>883031H09M010</td><td>1m</td></tr> <tr><td>111</td><td>1200658764</td><td>883031H09M020</td><td>2m</td></tr> <tr><td>112</td><td>1200658765</td><td>883031H09M030</td><td>3m</td></tr> <tr><td>113</td><td>1200669349</td><td>883031H09M030H</td><td>3m</td></tr> <tr><td>114</td><td>1200658766</td><td>883031H09M040</td><td>4m</td></tr> <tr><td>115</td><td>1200658767</td><td>883031H09M050</td><td>5m</td></tr> <tr><td>116</td><td>1200658768</td><td>883031H09M100</td><td>10m</td></tr> <tr><td>117</td><td>1200070140</td><td>883031P03M003</td><td>0.3m</td></tr> <tr><td>118</td><td>1200070141</td><td>883031P03M006</td><td>0.6m</td></tr> <tr><td>119</td><td>1200070142</td><td>883031P03M010</td><td>1m</td></tr> </table>				110	1200658763	883031H09M010	1m	111	1200658764	883031H09M020	2m	112	1200658765	883031H09M030	3m	113	1200669349	883031H09M030H	3m	114	1200658766	883031H09M040	4m	115	1200658767	883031H09M050	5m	116	1200658768	883031H09M100	10m	117	1200070140	883031P03M003	0.3m	118	1200070141	883031P03M006	0.6m	119	1200070142	883031P03M010	1m	E
5	1200070132	883031I03M003	0.3m																																																																																																																																																																										
6	1200070133	883031I03M006	0.6m																																																																																																																																																																										
7	1200070134	883031I03M010	1m																																																																																																																																																																										
8	1200070136	883031I03M020	2m																																																																																																																																																																										
9	1200070137	883031I03M030	3m																																																																																																																																																																										
10	1200070138	883031I03M050	5m																																																																																																																																																																										
11	1200070152	883031S20M010	1m																																																																																																																																																																										
12	1200070153	883031S20M020	2m																																																																																																																																																																										
13	1200070156	883031S20M050	5m																																																																																																																																																																										
40	1200659115	884031I20M005Y	0.5m																																																																																																																																																																										
41	1200660374	884031K05M005	0.5m																																																																																																																																																																										
42	1200660375	884031K05M006	0.6m																																																																																																																																																																										
43	1200660376	884031K05M010	1m																																																																																																																																																																										
44	1200660377	884031K05M015	1.5m																																																																																																																																																																										
45	1200660378	884031K05M020	2m																																																																																																																																																																										
46	1200660379	884031K05M030	3m																																																																																																																																																																										
47	1200660380	884031K05M040	4m																																																																																																																																																																										
48	1200660381	884031K05M050	5m																																																																																																																																																																										
49	1200660382	884031K05M060	6m																																																																																																																																																																										
75	1200668071	884031S20M020	2m																																																																																																																																																																										
76	1200668191	883031S20M030	3m																																																																																																																																																																										
77	1200668237	883031S20M100	10m																																																																																																																																																																										
78	1200668258	883031I03M080	8m																																																																																																																																																																										
79	1200668287	884031I20M025	2.5m																																																																																																																																																																										
80	1200668667	884031I20M030Y	3m																																																																																																																																																																										
81	1200070443	884021S20M003	0.3m																																																																																																																																																																										
82	1200070444	884021S20M006	0.6m																																																																																																																																																																										
83	1200070445	884021S20M010	1m																																																																																																																																																																										
84	1200070446	884021S20M020	2m																																																																																																																																																																										
110	1200658763	883031H09M010	1m																																																																																																																																																																										
111	1200658764	883031H09M020	2m																																																																																																																																																																										
112	1200658765	883031H09M030	3m																																																																																																																																																																										
113	1200669349	883031H09M030H	3m																																																																																																																																																																										
114	1200658766	883031H09M040	4m																																																																																																																																																																										
115	1200658767	883031H09M050	5m																																																																																																																																																																										
116	1200658768	883031H09M100	10m																																																																																																																																																																										
117	1200070140	883031P03M003	0.3m																																																																																																																																																																										
118	1200070141	883031P03M006	0.6m																																																																																																																																																																										
119	1200070142	883031P03M010	1m																																																																																																																																																																										
D	<table> <tr><td>14</td><td>1200070522</td><td>884031I03M020</td><td>2m</td></tr> <tr><td>15</td><td>1200070523</td><td>884031I03M030</td><td>3m</td></tr> <tr><td>16</td><td>1200070534</td><td>884031S20M030</td><td>3m</td></tr> <tr><td>17</td><td>1200070651</td><td>884031I03M006</td><td>0.6m</td></tr> <tr><td>18</td><td>1200070768</td><td>884031S20M050</td><td>5m</td></tr> <tr><td>19</td><td>1200070783</td><td>884031S20M100H</td><td>10m</td></tr> <tr><td>20</td><td>1200071138</td><td>884031S20M010H</td><td>1m</td></tr> <tr><td>21</td><td>1200071139</td><td>884031S20M020H</td><td>2m</td></tr></table>	14	1200070522	884031I03M020	2m	15	1200070523	884031I03M030	3m	16	1200070534	884031S20M030	3m	17	1200070651	884031I03M006	0.6m	18	1200070768	884031S20M050	5m	19	1200070783	884031S20M100H	10m	20	1200071138	884031S20M010H	1m	21	1200071139	884031S20M020H	2m																																																																																																																																												
14	1200070522	884031I03M020	2m																																																																																																																																																																										
15	1200070523	884031I03M030	3m																																																																																																																																																																										
16	1200070534	884031S20M030	3m																																																																																																																																																																										
17	1200070651	884031I03M006	0.6m																																																																																																																																																																										
18	1200070768	884031S20M050	5m																																																																																																																																																																										
19	1200070783	884031S20M100H	10m																																																																																																																																																																										
20	1200071138	884031S20M010H	1m																																																																																																																																																																										
21	1200071139	884031S20M020H	2m																																																																																																																																																																										

No.	Part No	Engineering No.	Cable Length
36	1200072725	885031I26M005	0.5m
37	1200072726	885031I26M010	1m
38	1200659070	884031I20M010Y	1m
39	1200659071	884031I20M015Y	1.5m
40	1200659115	884031I20M005Y	0.5m
41	1200660374	884031K05M005	0.5m
42	1200660375	884031K05M006	0.6m
43	1200660376	884031K05M010	1m
44	1200660377	884031K05M015	1.5m
45	1200660378	884031K05M020	2m
46	1200660379	884031K05M030	3m
47	1200660380	884031K05M040	4m
48	1200660381	884031K05M050	5m
49	1200660382	884031K05M060	6m
50	1200660383	884031S20M010	1m
51	1200660546	884031K05M100	10m
52	1200661046	885031K03M010	1m
53	1200661047	885031K03M020	2m
54	1200661049	885031K03M040	4m
55	1200661050	885031K03M050	5m
56	1200661769	884031K05M150	15m
57	1200669556	885031P03M015	1.5m
58	1200660969	884031K03M003	0.3m
59	1200661481	884031K03M120	12m
60	1200660971	884031K03M006	0.6m
61	1200660973	884031K03M010	1m
62	1200660975	884031K03M015	1.5m
63	1200660976	884031K03M020	2m
64	1200660977	884031K03M030	3m
65	1200660978	884031K03M040	4m
66	1200660980	884031K03M050	5m
67	1200660982	884031K03M060	6m
68	1200660983	884031K03M070	7m
69	1200660984	884031K03M090	9m
70	1200660985	884031K03M100	10m

No.	Part No.	Engineering No.	Cable Length
71	1200665039	884031S20M003	0.3m
72	1200665053	884031S20M060H	6m
73	1200665074	884031K05M080	8m
74	1200668052	883031S20M006	0.6m
75	1200668071	884031S20M020	2m
76	1200668191	883031S20M030	3m
77	1200668237	883031S20M100	10m
78	1200668258	883031I03M080	8m
79	1200668287	884031I20M025	2.5m
80	1200668667	884031I20M030Y	3m
81	1200070443	884021S20M003	0.3m
82	1200070444	884021S20M006	0.6m
83	1200070445	884021S20M010	1m
84	1200070446	884021S20M020	2m
85	1200070447	884021S20M030	3m
86	1200070449	884021S20M050	5m
87	1200668160	883021S20M010	1m
88	1200668608	883031E02M020	2m
89	1200668613	883031E02M030	3m
90	1200659035	883031E02M050	5m
91	1200668612	883031E02M100	10m
92	1200668908	883031E03M003H	0.3m
93	1200070118	883031E03M006	0.6m
94	1200668909	883031E03M006H	0.6m
95	1200070119	883031E03M010	1m
96	1200668910	883031E03M010H	1m
97	1200070945	883031E03M015	1.5m
98	1200668967	883031E03M015H	1.5m
99	1200070121	883031E03M020	2m
100	1200072445	883031E03M020H	2m
101	1200070123	883031E03M030	3m
102	1200668911	883031E03M030H	3m
103	1200072164	883031E03M040	4m
104	1200668968	883031E03M040H	4m
105	1200070125	883031E03M050	5m

Pos.	Part No.	Engineering No.	Cable Length
106	1200668912	883031E03M050H	5m
107	1200668175	883031E03M060	6m
108	1200070127	883031E03M100	10m
109	1200658762	883031H09M006	0.6m
110	1200658763	883031H09M010	1m
111	1200658764	883031H09M020	2m
112	1200658765	883031H09M030	3m
113	1200669349	883031H09M030H	3m
114	1200658766	883031H09M040	4m
115	1200658767	883031H09M050	5m
116	1200658768	883031H09M100	10m
117	1200070140	883031P03M003	0.3m
118	1200070141	883031P03M006	0.6m
119	1200070142	883031P03M010	1m
120	1200668324	883031P03M010G	1m
121	1200071121	883031P03M010H	1m
122	1200070143	883031P03M020	2m
123	1200668325	883031P03M020G	2m
124	1200668753	883031P03M020H	2m
125	1200070144	883031P03M030	3m
126	1200668326	883031P03M030G	3m
127	1200070145	883031P03M050	5m
128	1200668520	883031P03M070	7m
129	1200070146	883031P03M100	10m
130	1200070507	884031E03M003	0.3m
131	1200070508	884031E03M006	0.6m
132	1200070509	884031E03M010	1m
133	1200668361	884031E03M015	1.5m
134	1200070511	884031E03M020	2m
135	1200070512	884031E03M030	3m
136	1200669260	884031E03M030H	3m
137	1200070904	884031E03M050	5m
138	1200071157	884031E03M060	6m
139	1200071278	884031E03M100	10m
140	1200072011	884031E03M200	20m
141	1200668669	884031H09M006	0.6m
142	1200668846	884031H09M008	0.8m

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION													
DIMENSION UNITS		SCALE		CURRENT REV DESC: REMOVED OBSOLETE PART NUMBER AS PER PCN#517152			molex						
mm		1:1											
GENERAL TOLERANCES (UNLESS SPECIFIED)				CSE M12 XP AC FE RA MA STR XM DE									
ANGULAR TOL ± 1.0 °													
4 PLACES		±									EC NO: 840847		
3 PLACES		±									DRWN: PONNAM 2025/11/21		
2 PLACES		± 0.05									CHK'D: GGA 2025/11/25		
1 PLACE		± 0.3		APPR: GGA 2025/11/25			PRODUCT CUSTOMER DRAWING						
0 PLACES		± 0.5		INITIAL REVISION:			DOCUMENT NUMBER		DOC TYPE	DOC PART	REVISION		
DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS				DRWN: JMARSZALEK 2016/10/06		1200660973		PSD	000	A12			
				APPR: RSILLER 2016/12/08									
THIRD ANGLE PROJECTION				DRAWING		SERIES		MATERIAL NUMBER		CUSTOMER	SHEET NUMBER		
				A3-SIZE		120066				GENERAL MARKET	3 OF 4		

FORMAT: master-tb-prod-A3
REVISION: J1
DATE: 2021/05/01

10		9		8		7		6		5		4		3		2		1	
F	Pos.		Part No.		Engineering No.		Cable Length		Pos.		Part No.		Engineering No.		Cable Length				F
	143		1200668210		884031H09M009		0.9m		191		1200656208		888031H08C250		2.5m				
	144		1200668484		884031H09M010		1m		192		1200656209		888031H08M005		0.5m				
	145		1200668848		884031H09M013		1.3m		193		1200656210		888031H08M008		0.8m				
	146		1200668488		884031H09M015		1.5m		194		1200656211		888031H08M012		1.2m				
E	147		1200668845		884031H09M018		1.8m		195		1200656212		888031H08M015		1.5m				E
	148		1200668212		884031H09M020		2m		196		1200070057		883021E03M006		0.6m				
	149		1200668847		884031H09M021		2.1m		197		1200070058		883021E03M020		2m				
	150		1200668215		884031H09M030		3m		198		1200070439		884021P03M006		0.6m				
	151		1200668670		884031H09M050		5m		199		1200070440		884021P03M010		1m				
D	152		1200668671		884031H09M100		10m		200		1200070441		884021P03M020		2m				D
	153		1200070526		884031P03M003		0.3m		201		1200070442		884021P03M030		3m				
	154		1200070527		884031P03M006		0.6m		202		1200070870		883021P03M050		5m				
	155		1200060056		884031P03M010		1m		203		1200072191		883021E03M030		3m				
	156		1200060057		884031P03M020		2m		204		1200072198		883021E03M050		5m				
C	157		1200070529		884031P03M030		3m		205		1200665038		884021E03M050		5m				C
	158		1200071187		884031P03M050		5m		206		1200668061		884021E03M006		0.6m				
	159		1200072012		884031P03M100		10m		207		1200668219		884021E03M030		3m				
	160		1300288001		885031D12M020		2m		208		1200668673		888031E02M0041		0.4m				
	161		1200668658		885031E02M020		2m		209		1200669541		884031P03M015		1.5m				
B	162		1200668610		885031E02M050		5m		210		1200669885		884031E03M004		0.4m				B
	163		1200668660		885031E02M100		10m		211		1200669886		884031E03M005		0.5m				
	164		1200668339		885031E03M006		0.6m		212		1200669887		884031E03M013		1.3m				
	165		1200668189		885031E03M010		1m		213		1200669888		884031E03M080		8m				
	166		1200668278		885031E03M020		2m		214		1200070510		883031E03M070		7m				
A	167		1200668340		885031E03M030		3m												A
	168		1200668279		885031E03M050		5m												
	169		1200668653		885031E03M070		7m												
	170		1200668348		885031E03M100		10m												
	171		1200668761		885031E03M150		15m												
172		1200669229		885031H09C250		25m													
173		1200668512		885031H09M006		0.6m													
174		1200668496		885031H09M010		1m													
175		1200668513		885031H09M020		2m													
176		1200668514		885031H09M030		3m													
177		1200668515		885031H09M050		5m													
178		1200668516		885031H09M100		10m													
179		1200073085		885031P03M006		0.6m													
180		1200668188		885031P03M010		1m													
181		1200072376		885031P03M0105		1m													
182		1200070917		885031P03M020		2m													
183		1200668091		885031P03M025		2.5m													
184		1200070919		885031P03M030		3m													
185		1200668273		885031P03M050		5m													
186		1200073086		885031P03M100		10m													
187		1200070434		884021E03M020		2m													
188		1200658319		888031H08M050		5m													
189		1200668673		888031E02M0041		0.4m													
190		1200668849		888031P02M150		15m													
DOCUMENT STATUS		P1		RELEASE DATE		2025/11/25		05:37:48											
10		9		8		7		6		5		4		3		2		1	

147

1200668845

884031H09M018

1.8m

148

1200668212

884031H09M020

2m

149

1200668847

884031H09M021

2.1m

150

1200668215

884031H09M030

3m

151

1200668670

884031H09M050

5m

152

1200668671

884031H09M100

10m

153

1200070526

884031P03M003

0.3m

154

1200070527

884031P03M006

0.6m

155

1200060056

884031P03M010

1m

156

1200060057

884031P03M020

2m

157

1200070529

884031P03M030

3m

158

1200071187

884031P03M050

5m

159

1200072012

884031P03M100

10m

160

1300288001

885031D12M020

2m

161

1200668658

885031E02M020

2m

162

1200668610

885031E02M050

5m

163

1200668660

885031E02M100

10m

164

1200668339

885031E03M006

0.6m

165

1200668189

885031E03M010

1m

166

1200668278

885031E03M020

2m

167

1200668340

885031E03M030

3m

168

1200668279

885031E03M050

5m

169

1200668653

885031E03M070

7m

170

1200668348

885031E03M100

10m

171

1200668761

885031E03M150

15m

172

1200669229

885031H09C250

25m

173

1200668512

885031H09M006

0.6m

174

1200668496

885031H09M010

1m

175

1200668513

885031H09M020

2m

176

1200668514

885031H09M030

3m

177

1200668515

885031H09M050

5m

178

1200668516

885031H09M100

10m

179

1200073085

885031P03M006

0.6m

180

1200668188

885031P03M010

1m

181

1200072376

885031P03M0105

1m

182

1200070917

885031P03M020

2m

183

1200668091

885031P03M025

2.5m

184

1200070919

885031P03M030

3m

185

1200668273

885031P03M050

5m

186

1200073086

885031P03M100

10m

187

1200070434

884021E03M020

2m

188

1200658319

888031H08M050

5m

189

1200668673

888031E02M0041

0.4m

190

1200668849

888031P02M150

15m

Pos.

Part No.

Engineering No.

Cable Length

191

1200656208

888031H08C250

2.5m

192

1200656209

888031H08M005

0.5m

193

1200656210

888031H08M008

0.8m

194

1200656211

888031H08M012

1.2m

195

1200656212

888031H08M015

1.5m

196

1200070057

883021E03M006

0.6m

197

1200070058

883021E03M020

2m

198

1200070439

884021P03M006

0.6m

199

1200070440

884021P03M010

1m

200

1200070441

884021P03M020

2m

201

1200070442

884021P03M030

3m

202

1200070870

883021P03M050

5m

203

1200072191

883021E03M030

3m

204

1200072198

883021E03M050

5m

205

1200665038

884021E03M050

5m

206

1200668061

884021E03M006

0.6m

207

1200668219

884021E03M030

3m

208

1200668673

888031E02M0041

0.4m

209

1200669541

884031P03M015

1.5m

210

1200669885

884031E03M004

0.4m

211

1200669886

884031E03M005

0.5m

212

1200669887

884031E03M013

1.3m

213

1200669888

884031E03M080

8m

214

1200070510

883031E03M070

7m

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION

DIMENSION UNITS

SCALE

mm

1:1

GENERAL TOLERANCES (UNLESS SPECIFIED)

ANGULAR TOL

±

1.0 °

4 PLACES

±

3 PLACES

±

2 PLACES

±

0.05

1 PLACE

±

0.3

0 PLACES

±

0.5

DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS

THIRD ANGLE PROJECTION

DRAWING

SERIES

A3-SIZE

120066

CURRENT REV DESC: REMOVED OBSOLETED PART NUMBER AS PER PCN#517152

EC NO: 840847

DRWN: PONNAM

CHK'D: GGA

APPR: GGA

2025/11/21

2025/11/25

2025/11/25

INITIAL REVISION:

DRWN: JMARSZALEK

APPR: RSILLER

2016/10/06

2016/12/08

DOCUMENT NUMBER

1200660973

DOC TYPE

PSD

DOC PART

000

REVISION

A12

CSE M12 XP AC FE RA MA STR XM DE

PRODUCT CUSTOMER DRAWING

GENERAL MARKET

4 OF 4

DOCUMENT STATUS

P1

RELEASE DATE

2025/11/25

05:37:48

9

8

7

6

5

4

3

2

1

FORMAT: master-b-prod-A3

REVISION: 11

DATE: 2021/05/01

9

8

7

6

5

4

3

2

1