


PU SERIES – UL 6P/IP68 PC ENCLOSURE

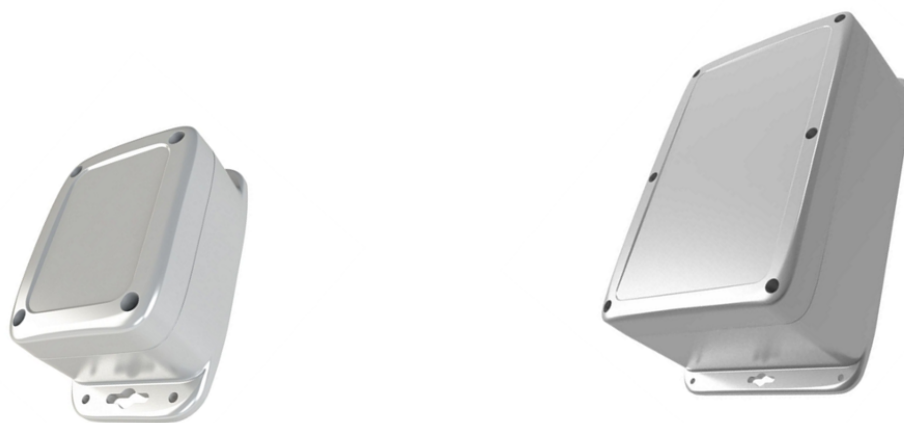

Ordering Information

Part Number	External Length (in)	External Width (in)	External Depth (in)	Weight
PU-16565	6.50	3.20	3.30	0.30
PU-16569	7.60	4.60	2.20	0.40
PU-16575	8.70	5.20	2.40	0.50
PU-16585	12.00	9.00	4.20	0.60

Priced, sold and packaged in quantities of one

Benefits and Features

- Modern streamlined design with multiple sizes to choose from
- Rated to NEMA 4X & 6P and Meets IP66 & IP68 requirements
- UL Listed to UL 508A, Type 1, 2, 4, 4X, 6, 6P, 12 & 13
- Designed and tested for a wide variety of outdoor applications and adverse conditions
- Molded from durable, UV stabilized polycarbonate UL94 V0 rated
- Continuous silicone rubber gasket is pre-installed to ensure watertight seal
- Stainless steel screws and brass inserts for cover assembling
- Mounting bosses in base
- All sizes include molded flanges for enclosure mounting

BUD PU SERIES

Budind.com

Accessories

- 0.060" Aluminum internal mounting panel (PUX prefix)

Applications


- PCB indoor/outdoor housing

Competition and Competitive Advantages

- Non-metallic IP68 / NEMA 6P enclosures
- UL94 V0 rating
- UV resistant for outdoor applications

Availability

BUD PU SERIES

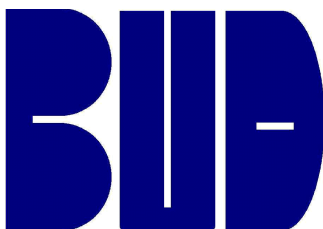

Bud Industries, Inc.