


WPANT50410-S2A

RP-SMA Female Bulkhead (IP67) to MHF 4L Cable Assembly

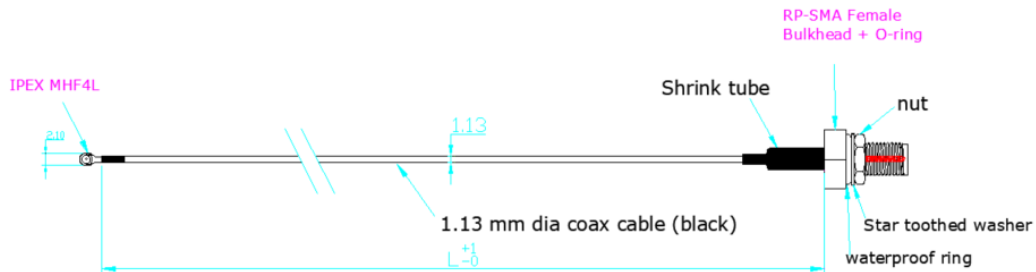

Description

This is a standard 1.13 dia coax cable assembly with an RP-SMA female bulkhead connector (IP67 compliant) on one end and IPX MHF-4L connector on the other.

We specialize in developing customized Antenna solutions. Please contact sales@worldproducts.com with your specific application requirements.

Electrical Properties

Operating Frequency	DC – 6 GHz
Attenuation (dB/ft)	0.9 dB @ 900MHz, and 1.4dB @ 2400 MHz
Input / Output Impedance [Ω]	50Ω

Mechanical / Environmental Properties

Cable Type	1.13 mm OD micro coaxial
Cable Length (L)	8 inches
Connector 1	RP SMA F bulkhead (with O-ring)
Connector 2	IPX MHF 4L
Operating / Storage Temperature	-40°C to +150°C
Environmental	Meets standards for UL 94V-0, IP67
Hazardous Materials	RoHS Compliant