


Cable glands Progress® nickel-plated brass

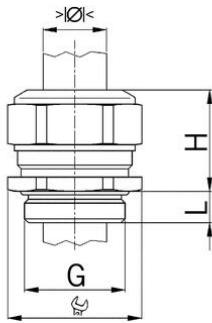

Short entry thread metric

Type approval: Progress MS

- One-piece sealing insert
- not overall length insulated

Order number:	1000.10.060
E-No:	121079218
EAN:	7611614104232
Material	Nickel-plated brass
Seal	TPE / NBR
O-ring	NBR
Operation temperature	-40°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Entry thread	M10x1.5
Clamping range min.	4.0 mm
Clamping range max.	6.0 mm
Wrench size	13 mm
Dimension H	15 mm
Thread length L	5 mm
Note	1
UL - clamping range	6.0-6.0 mm
Dispatch	50

1 = Metric coarse-pitch thread (with VDE test report)

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.