


Cable glands Progress® nickel-plated brass with sealing insert without drilled

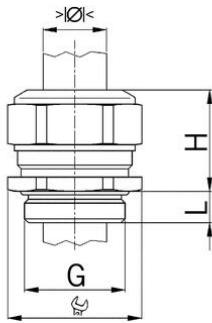

Short entry thread metric

- For high temperature applications
- One-piece solid sealing insert
- not overall length insulated

Order number:	1000.20.30.91
E-No:	121145508
EAN:	7611614131771
Material	Nickel-plated brass
Seal	FPM, without drilled hole
O-ring	FPM
Operation temperature	-40°C / +200°C
Protection class	IP 68 (up to 10 bar) / IP 69
Entry thread	M20x1.5
Clamping range without insert max.	15.0 mm
Wrench size	24 mm
Dimension H	23 mm
Thread length L	6 mm
Dispatch	50

1 = Metric coarse-pitch thread

When frozen to at least -25°C, the solid sealing inserts are easy to drill.