


Metal protection conduit for Ex Applications

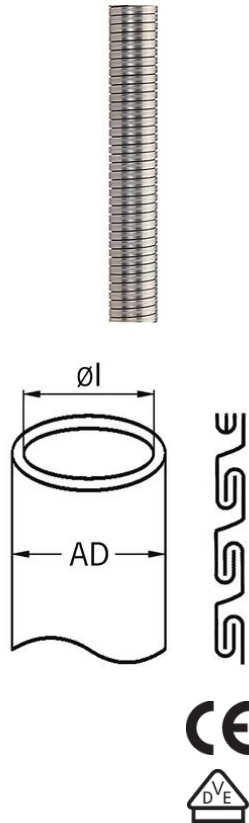

Protective metal conduit non liquid-tight

- Protective metal conduit non liquid-tight
- FLEXAgraff®-AS

Order number:	1080.101.040
E-No:	125451799
EAN:	7611614154237
Material	Steel galvanized, double-overlapped
Properties	High tensile, torsional- and bending strength, highly flexible, no untwisting of the conduit
Application	Machine and plant constructions, vehicle construction, shipbuilding, automation, electrical installations
Tested acc. to	EN / IEC 61386-23
Protection class	IP 40
Operation temperature	-50°C / +250°C
Outer diameter	45 mm
Inner diameter	40 mm
Bending radius static	150 mm
Bending radius dynamic	375 mm
Bushing	5031.027.036
Dispatch	25

Available on request:

- Stainless steel A2