


Cable glands Progress® EMC Rapid nickel-plated brass with contact disc

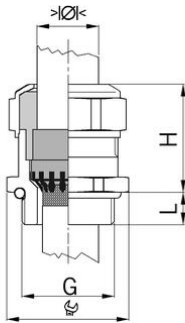

Short entry thread metric

Type approval: Progress MS EMV Rapid

- One-piece sealing insert
- not overall length insulated

Order number:	1081.12.075
E-No:	121072238
EAN:	7611614207018
Material	Nickel-plated brass
Contact sleeve	Nickel-plated brass
Contact disc	Stainless steel A2
Seal	TPE
O-ring	NBR
Operation temperature	-40°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Properties	For a quick installation of partially dismantled cables as well as thoroughly shielded cables
Entry thread	M12x1.5
Clamping range without insert min.	6.0 mm
Clamping range without insert max.	7.5 mm
Wrench size	15 mm
Dimension H	20 mm
Thread length L	5 mm
Dispatch	50

