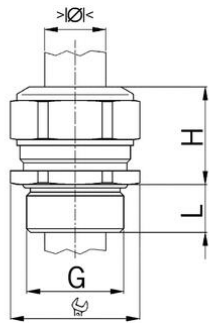


Cable glands Progress® nickel-plated brass

**Long entry thread Pg****Type approval: Progress MS**

- One-piece sealing insert
- not overall length insulated

| | |
|-----------------------|------------------------------|
| Order number: | 1100.16.150 |
| E-No: | 121095428 |
| EAN: | 7611614107882 |
| Material | Nickel-plated brass |
| Seal | TPE |
| O-ring | NBR |
| Operation temperature | -40°C / +100°C |
| Protection class | IP 68 (up to 10 bar) / IP 69 |
| NEMA Type rating | 4X |
| Entry thread | Pg 16 |
| Clamping range min. | 11.0 mm |
| Clamping range max. | 15.0 mm |
| Wrench size | 24 mm |
| Dimension H | 23 mm |
| Thread length L | 10 mm |
| UL - clamping range | 13.0-15.0 mm |
| Dispatch | 50 |

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.