


Cable glands Progress® nickel-plated brass with special entry thread

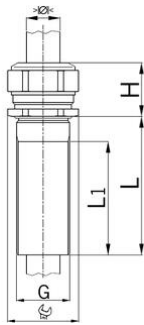

Extra-long entry thread metric

Type approval: Progress MS L

- Two-piece sealing insert
- not overall length insulated

Order number:	1100.17.50
E-No:	121340408
EAN:	7611614124117
Material	Nickel-plated brass
Seal	TPE
O-ring	NBR
Operation temperature	-40°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
Entry thread	M16x1.5
Clamping range with insert min.	6.0 mm
Clamping range with insert max.	8.0 mm
Clamping range without insert min.	8.0 mm
Clamping range without insert max.	10.5 mm
Wrench size	24/18 mm
Dimension H	22 mm
Dimension L1	40
Thread length L	50 mm
Dispatch	10

Further dimensions upon request