


Cable glands Progress® nickel-plated brass

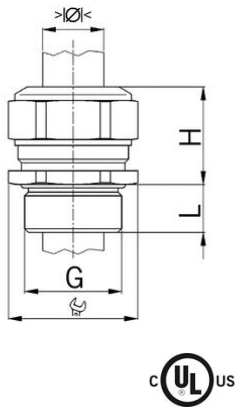

Long entry thread Pg

Type approval: Progress MS

- One-piece sealing insert
- not overall length insulated

Order number:	1100.48.370
E-No:	121095808
EAN:	7611614108018
Material	Nickel-plated brass
Seal	TPE
O-ring	NBR
Operation temperature	-40°C / +100°C
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Entry thread	Pg 48
Clamping range min.	32.0 mm
Clamping range max.	37.0 mm
Wrench size	65 mm
Dimension H	37 mm
Thread length L	15 mm
UL - clamping range	32.0-37.0 mm
Dispatch	10

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.