


## O-rings and sealing washers

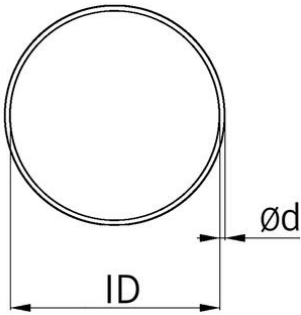

### O-rings for high temperatures

- suitable for entry thread metric or Pg

<b>Article no:</b>	<b>1136.98.08</b>
EAN:	7611614028781
Material	FPM
Operation temperature	-40°C / +200°C
Entry thread	Pg 36
Inner diameter	42.5 mm
Diameter	2.6 mm
Dispatch	1