


## Cable glands Progress® nickel-plated brass

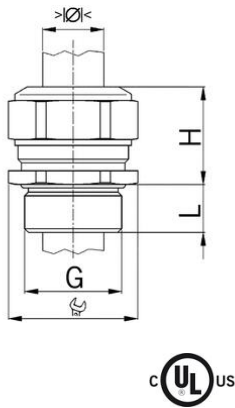

### Long entry thread Pg

#### Type approval: Progress MS

- One-piece sealing insert
- overall length insulated

|                       |                              |
|-----------------------|------------------------------|
| <b>Order number:</b>  | <b>1160.21.190</b>           |
| E-No:                 | 121093508                    |
| EAN:                  | 7611614115610                |
| Material              | Nickel-plated brass          |
| Seal                  | TPE                          |
| O-ring                | NBR                          |
| Operation temperature | -40°C / +100°C               |
| Protection class      | IP 68 (up to 10 bar) / IP 69 |
| NEMA Type rating      | 4X                           |
| Entry thread          | Pg 21                        |
| Clamping range min.   | 16.0 mm                      |
| Clamping range max.   | 19.0 mm                      |
| Wrench size           | 30 mm                        |
| Dimension H           | 28 mm                        |
| Thread length L       | 12 mm                        |
| UL - clamping range   | 17.0-19.0 mm                 |
| Dispatch              | 25                           |

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.