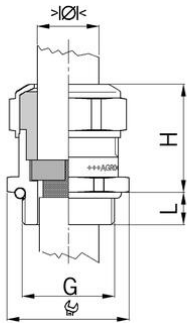


## Cable glands Progress® EMC easyCONNECT nickel-plated brass with contact

**Long entry thread metric****Type approval: Progress EMV easyCONNECT**

- Two-piece sealing insert
- not overall length insulated

<b>Order number:</b>	<b>1183.12.050</b>
E-No:	121082408
EAN:	7611614249759
Material	Nickel-plated brass
Contact spring	Spring steel 1.4310
Seal	TPE
O-ring	NBR
Operation temperature	-60°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Properties	For a quick and safe installation of partially dismantled cables as well as thoroughly shielded cables
Entry thread	M12x1.5
Clamping range with insert min.	- mm
Clamping range with insert max.	- mm
Clamping range without insert min.	3.5 mm
Clamping range without insert max.	5.0 mm
Wrench size	15 mm
Dimension H	22 mm
Thread length L	10 mm
Additional note	1
Dispatch	50

1 = One-piece sealing insert

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.

**Available on request:**

- Entry thread Pg and NPT
- Executions in steel A2 and A4