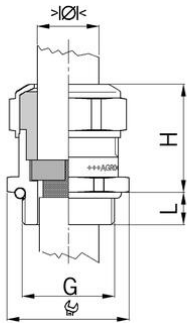


Cable glands Progress® EMC easyCONNECT nickel-plated brass with contact

**Long entry thread metric****Type approval: Progress EMV easyCONNECT**

- Two-piece sealing insert
- not overall length insulated

Order number:	1183.25
E-No:	121082708
EAN:	7611614249797
Material	Nickel-plated brass
Contact spring	Spring steel 1.4310
Seal	TPE
O-ring	NBR
Operation temperature	-60°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Properties	For a quick and safe installation of partially dismantled cables as well as thoroughly shielded cables
Entry thread	M25x1.5
Clamping range with insert min.	12.5 mm
Clamping range with insert max.	16.0 mm
Clamping range without insert min.	16.0 mm
Clamping range without insert max.	20.5 mm
Wrench size	30 mm
Dimension H	33 mm
Thread length L	11 mm
Additional note	-
Dispatch	25

1 = One-piece sealing insert

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.

Available on request:

- Entry thread Pg and NPT
- Executions in steel A2 and A4