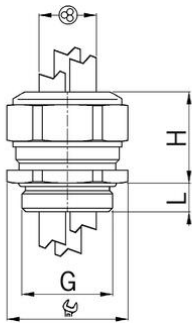


## Cable glands Progress® nickel-plated brass for installation of multiple cables

**Short entry thread metric****Type approval: Progress MS Multi**

- One-piece sealing insert
- not overall length insulated

|                                    |                            |
|------------------------------------|----------------------------|
| <b>Order number:</b>               | <b>1310.20.2.075</b>       |
| E-No:                              | 121161528                  |
| EAN:                               | 7611614139555              |
| Material                           | Nickel-plated brass        |
| Seal                               | TPE                        |
| O-ring                             | NBR                        |
| Operation temperature              | -40°C / +100°C             |
| Strain relief                      | Version A acc. to EN 62444 |
| Protection class                   | IP 68                      |
| Entry thread                       | M20x1.5                    |
| Clamping range without insert min. | 5.5 mm                     |
| Clamping range without insert max. | 7.5 mm                     |
| Number of cables                   | 2                          |
| Wrench size                        | 24 mm                      |
| Dimension H                        | 23 mm                      |
| Thread length L                    | 6 mm                       |
| Dispatch                           | 50                         |

Further versions and entry threads are available upon request.

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.