


Synthetic cable glands Syntec® with lamellar technology

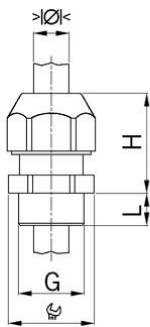

Long entry thread metric

Type approval: SYNTEC

- Black RAL 9005
- One-piece sealing ring

Order number:	1545.40.1.33
E-No:	121766029
EAN:	7611614117041
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	TPE or CR (Neoprene)
Operation temperature	-30°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68
NEMA Type rating	4X
Entry thread	M40x1.5
Clamping range min.	22.0 mm
Clamping range max.	33.0 mm
Wrench size	53 mm
Dimension H	48 mm
Thread length L	15 mm
UL - clamping range	26.0-26.0 mm
Dispatch	10