


Synthetic cable glands Syntec® with lamellar technology

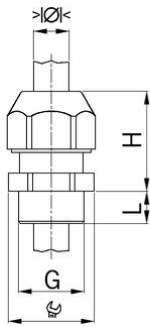

Long entry thread metric

Type approval: SYNTEC

- Light grey RAL 7035
- One-piece sealing ring

Order number:	1555.20.1.13
E-No:	121762618
EAN:	7611614230627
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	TPE or CR (Neoprene)
Operation temperature	-30°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68
NEMA Type rating	4X
Entry thread	M20x1.5
Clamping range min.	7.0 mm
Clamping range max.	13.0 mm
Wrench size	24 mm
Dimension H	29 mm
Thread length L	15 mm
UL - clamping range	8.0-13.0 mm
Dispatch	50

Available on request:

- Dark grey RAL 7001