


Synthetic cable glands Progress® GFK for installation of multiple cables

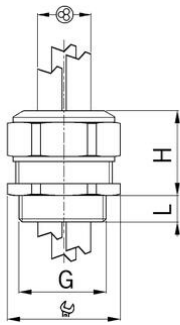

Entry thread Pg

- Light grey RAL 7035
- One-piece sealing insert

Order number:	1571.13.2.060
EAN:	7611614147673
Material	Polyamide glass fiber reinforced
Properties	halogen-free
Seal	TPE
Operation temperature	-20°C / +100°C
Protection class	IP 68
Entry thread	Pg 13
Clamping range without insert min.	4.5 mm
Clamping range without insert max.	6.0 mm
Number of cables	2
Wrench size	27 mm
Dimension H	28 mm
Thread length L	13 mm
Dispatch	50

Additional versions and colours are available upon request: e.g. dark grey RAL 7001, black RAL 9005, larger entry threads