


Synthetic cable glands Progress® GFK for installation of multiple cables

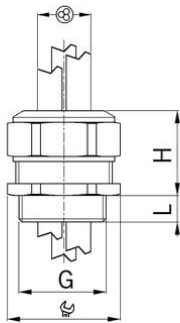

Entry thread metric

Type approval: Progress GFK multi

- Light grey RAL 7035
- One-piece sealing insert

Order number:	1571.32.3.105
E-No:	121690728
EAN:	7611614148090
Material	Polyamide glass fiber reinforced
Properties	halogen-free
Seal	TPE
Operation temperature	-20°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68
Entry thread	M32x1.5
Clamping range without insert min.	8.5 mm
Clamping range without insert max.	10.5 mm
Number of cables	3
Wrench size	41 mm
Dimension H	35 mm
Thread length L	15 mm
Dispatch	25

Additional versions and colours are available upon request: e.g. dark grey RAL 7001, black RAL 9005, larger entry threads