


Pressure balance element nickel-plated brass and synthetic

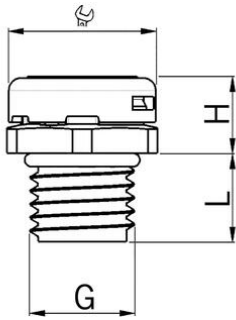

Synthetic pressure balance element with membrane

- with membrane
- Black RAL 9005

Order number:	2445.12
E-No:	126245300
EAN:	7611614270067
Material	Polyamide PA 6
Membrane	PES polyethersulfone
O-ring	NBR
Operation temperature	-40°C / +100°C
Protection class	IP 66 / IP 68 / IP 69
Water intrusion pressure	IP 68 = 0.2 bar / 30 min
Air flow rate	> 90 ml / min / cm ² at 10 mbar
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Entry thread	M12x1.5
Wrench size	17 mm
Dimension H	9 mm
Dimension L	10 mm
Dispatch	25