


EMC conduit gland for metal conduit SPR / FLEXAgraff

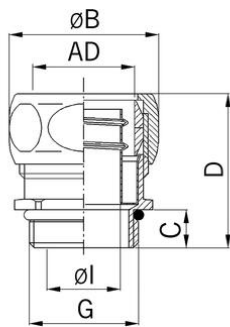

Complete EMC conduit connectors nickel-plated brass

- Conduit gland US-M
- for FLEXAgraff-CU-AS / SPR-EDU-AS
- with brass thrust collar

Order number:	5011.328.040
EAN:	7611614119137
Material	Nickel-plated brass
Bushing	Polished brass
Thrust collar	Polished brass
O-ring	NBR
Properties	Highly watertight and dustproof, friction locking of conduit and gland, proper earthing, covered conduit ends, resistant to stretch and vibrations
Protection class	IP 40
Operation temperature	-40°C / +250°C
Outer diameter	45 mm
Entry thread	M40x1.5
Diameter $\varnothing I$	35.0 mm
Diameter $\varnothing B$	57 mm
Dimension C	13 mm
Dimension D	43 mm
Wrench size	52/54 mm
Dispatch	20

1 = For SPR-EDU-AS

The reliability is only guaranteed with the corresponding stabilizing bush