


## Synthetic straight conduit connector

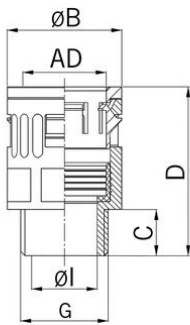

### Synthetic straight conduit connector

- Quick connector RQG-M
- Black

<b>Order number:</b>	<b>5020.037.220</b>
E-No:	126806501
EAN:	7611614095011
Material	Polyamide impact-resistant
Seal	TPE
Fire classification	V0 (UL 94)
Properties	Quick and pull-out-proof installation by means of the «push-in» lock, simple dismounting by displacing the snap-in sleeve
Protection class	IP 68 / IP 69
Operation temperature	-40°C / +120°C
Outer diameter	21.2 mm
Entry thread	M20x1.5
Diameter Ø I	16.0 mm
Diameter Ø B	29.5 mm
Dimension C	13.0 mm
Dimension D	44.5 mm
Wrench size	27 mm
Dispatch	50

#### Available on request:

- Executions with CTG or NPT entry thread