


Synthetic straight conduit connector

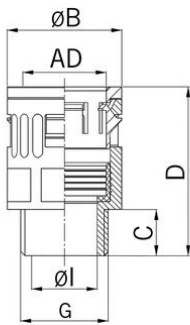

Synthetic straight conduit connector

- Quick connector RQG-M
- Black

Order number:	5020.037.225
E-No:	126806600
EAN:	7611614095042
Material	Polyamide impact-resistant
Seal	TPE
Fire classification	V0 (UL 94)
Properties	Quick and pull-out-proof installation by means of the «push-in» lock, simple dismounting by displacing the snap-in sleeve
Protection class	IP 68 / IP 69
Operation temperature	-40°C / +120°C
Outer diameter	28.5 mm
Entry thread	M25x1.5
Diameter Ø I	20.5 mm
Diameter Ø B	37.0 mm
Dimension C	13.0 mm
Dimension D	47.0 mm
Wrench size	34 mm
Dispatch	25

Available on request:

- Executions with CTG or NPT entry thread