


Conduit clamp small RQH

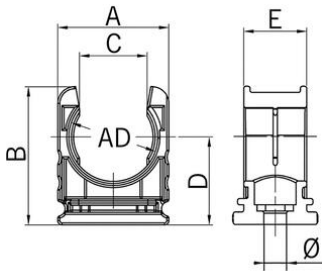

Conduit clamp small RQH

- Conduit clamp RQH
- Black

Order number:	5030.025.216
E-No:	126007516
EAN:	7611614169347
Material	Polyamide
Fire classification	V2 (UL 94)
Properties	With fixing ribs as strain relief
Application	Fastening with central screw or by insertion into a C-profile bar
Operation temperature	-40°C / +120°C
Outer diameter	21.2 mm
Dimension A	26.5 mm
Dimension B	33.0 mm
Dimension C	16.6 mm
Dimension D	21.0 mm
Dimension E	15.0 mm
Diameter	5.5 mm
Dispatch	50