


## Conduit clamp small RQH

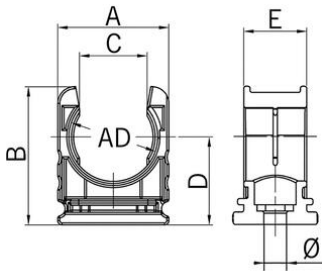

### Conduit clamp small RQH

- Conduit clamp RQH
- Black

<b>Order number:</b>	<b>5030.025.236</b>
E-No:	126007536
EAN:	7611614169415
Material	Polyamide
Fire classification	V2 (UL 94)
Properties	With fixing ribs as strain relief
Application	Fastening with central screw or by insertion into a C-profile bar
Operation temperature	-40°C / +120°C
Outer diameter	42.5 mm
Dimension A	54.5 mm
Dimension B	55.5 mm
Dimension C	30.1 mm
Dimension D	32.0 mm
Dimension E	20.0 mm
Diameter	6.5 mm
Dispatch	25