

IDC TYPE METAL SHELL (Black, Zinc)

- Metal, **Zinc** Plated Shell
- **Black** Plastic Fillings
- Gold Plated Contacts
- Metal Strain Relief



Female IDC-15FA

IDC TYPE METAL SHELL (Blue, Tin)

- Metal, **Tin** Plated Shell
- Metal Strain Relief
- **Blue** Plastic Fillings
- Gold Plated Contacts
- All Plugs with Grounding Indents On Shells
- Low Profile, 0.71" Total Thickness After Crimping
- Strain Relief Included



IDC-37MB

Strain Relief

IDC-37FB

Male IDC-(XX)MB

Metal IDC-(XX)B-SR

Female IDC-(XX)FB

Plastic IDC-(XX)P-SR

XX= Pins: 9, 15, 25, 37.

IDC ALL PLASTIC (Blue)

- **All Plastic** Construction
- Blue Plastic Fillings
- Gold Plated Contacts
- Strain Relief Included



IDC-9F-BLUE

Male IDC-(XX)M-BLUE

Female IDC-(XX)F-BLUE

XX= Pins: 9, 15, 25, 37.

Black IDC-15F-BK


Strain Relief Only

Metal IDC-(XX)B-SR XX= Pins: 9, 15, 25, 37.

Plastic IDC-(XX)P-SR XX= Pins: 9, 15, 25, 37.

IDC FOR DISCRETE WIRE

- All Plugs with Grounding Indents On Shells
- Metal, Tin Plated Shell
- 24-28 AWG Stranded Wire
- Gold Plated Contacts
- Clip by Hand, No Tool Needed

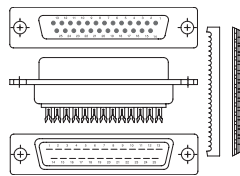

DSL-25P

Male **Female**

DSL-09P DSL-09S

DSL-15P DSL-15S

DSL-25P DSL-25S

IDC TYPE METAL SHELL (Blue, Tin)

- Metal Tin Plated Shell
- **Plastic** Strain Relief
- Gold Plated Contacts
- All Plugs with Grounding Indents On Shells
- Economy type



IDC-15FB/2

Male

Female

IDC-09MB/2

IDC-09FB/2

IDC-15MB/2

IDC-15FB/2

IDC-25MB/2

IDC-25FB/2

IDC-37MB/2

IDC-37FB/2

4/40 Threaded Insert

Male

Female

IDC-09MB/2-D

IDC-09FB/2-D

IDC-15MB/2-D

IDC-15FB/2-D

IDC-25MB/2-D

IDC-25FB/2-D



IDC-15MB/2

IDC TYPE ALL PLASTIC

- All Plastic Shell
- Female w/Bail Lock
- Gold plated Contacts
- Use Standard .05" Centered Ribbon Cable (See Pg. 109)



57F-36F

Male **Female**

57F-24M 57F-36F

57F-36M 57F-50F

57F-50M



57F-36M

IDC TYPE METAL SHELL

- Tin Plated Metal Shell
- Gold Plated Contacts
- Blue Plastic fillings
- Female W/Bail Lock
- Use Standard .05" Centered Ribbon Cable



57F-50FB

Male **Female**

57F-36MB 57F-24FB

57F-50MB 57F-36FB

57F-50FB



57F-50MB