


Bushings, Nipples, Locknuts and Plugs

Meets and surpasses NEC® requirements!

Insulated Throat Fittings

- Steel or malleable iron (steel through 1½")
- Exceeds NEC 373-6C requirements for protection of ungrounded connectors at entrance to raceways, pull boxes and junctions
- Recognizable by distinctive trademarked blue insulating liner in throat
- Reduces wire pulling effort by as much as 50%
- Temperature rating of 105° C
- Look for the unique T&B blue color, ensuring the highest quality fitting

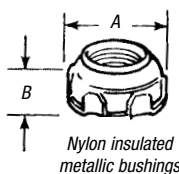

Nylon insulated metallic bushings

CAT. NO.		DIMENSIONS (IN.)		
STL. OR M.I.	ALUM.	SIZE	A	B
1222	1222AL	½"	1⅜	29/64
1223	1223AL	¾"	1⅝	31/64
1224	1224AL	1"	1⅞	11/32
1225	1225AL	1¼"	1⅞	21/32
1226	1226AL	1½"	2⅜	23/32
1227	1227AL	2"	2⅞	7/8
1228	1228AL	2½"	3⅞	1/2
1229	1229AL	3"	3⅞	5/16
1230	1230AL	3½"	4⅞	1/16
1231	1231AL	4"	4⅞	13/32
1232†	1232AL†	4½"	—	—
586	586AL	5"	5⅜	19/32
587	587AL	6"	7⅞	1⅞


† Not CSA Certified

Catalog series 1222 thru 1232, 586 and 587 are available in aluminum. Add suffix AL to Cat. No. The aluminum series fittings are not CSA certified.

Locknut-type base improves bonding and resists loosening under vibration.

Metallic Bushings

- Aluminum, steel or malleable iron (steel through 1½")
- Smoothly rounded shoulder covers end of conduit
- Broad flange covers knockout hole
- High ribs for easy tightening with fingers or with wrench
- ½" to 1½" sizes, formed in steel, feature extra-smooth shoulders

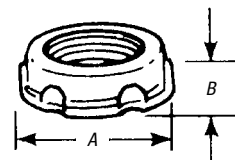

CAT. NO.		DIMENSIONS (IN.)		
STL. OR M.I.	ALUM.	SIZE	A	B
122	122AL	½"	1⅜	13/32
123	123AL*	¾"	1¼	7/16
124	124AL**	1"	1⅞	1/2
125-TB	125AL	1¼"	1⅞	9/16
126	126AL	1½"	2⅜	19/32
127	127AL	2"	2⅞	5/8
128	128AL	2½"	3⅞	3/4
129	129AL	3"	3⅞	13/16
130-TB	130AL	3½"	4⅞	15/16
131-TB	131AL	4"	4⅞	1
132-TB	—	4½"	5⅞	1⅞
133-TB	133AL	5"	6	1⅞
134-TB	134AL	6"	7¼	1¼

* Not UL Listed or CSA Certified

UL File No. E-23018


** Not CSA Certified

CSA File No. 2884

Available with DURA-PLATE® Finish.

Perfect threads for easy thread-on!

Plastic Insulating Bushings

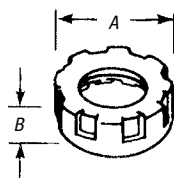

All Plastic Insulating Bushings

- Impact-resistant plastic insulation
- Ribbed for easy, secure gripping
- UL Listed 105° C



		DIMENSIONS (IN.)	
CAT. NO.	SIZE	A	B
222-TB	1/2"	1 1/16	3/8
223-TB	3/4"	1 9/32	13/32
224	1"	1 7/16	9/16
225-TB	1 1/4"	1 29/32	9/16
226	1 1/2"	2 1/32	9/16
227	2"	2 25/32	5/8
228-TB	2 1/2"	3 5/8	3/4
229-TB	3"	4 1/16	3/4
230-TB	3 1/2"	4 5/8	7/8
231	4"	5 1/8	7/8
232	4 1/2"	5 11/16	1
233	5"	6 7/16	1
234	6"	7 7/16	1

UL Rated flame retardant 94V-1