


Couplings and Accessories

One-piece fitting couples armored cable or flexible conduit to threaded rigid conduit!

TITE-BITE® Combination Couplings — Armored Cable for Threaded Rigid

- Tite-Bite® wedge holds conduit securely with a double grip
- When used with a Chase® nipple, this fitting will connect flexible conduit to outlet boxes, enabling more wiring space in the box than the usual connector
- UL® Listed as a grounding means under NEC® 350-5
- Malleable iron construction

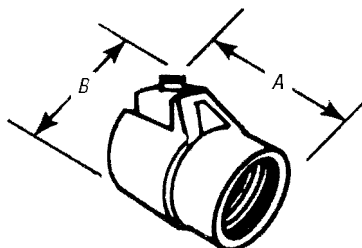

CAT. NO.	SIZE	DIMENSIONS (IN.)	
		A	B
440	1/2"	1 1/8	1 27/32
441	3/4"	1 1/4	2 1/8
442	1"	2	2 17/32


UL File No. E-23018

CSA File No. 2884

Mount flat against wall, eliminating the need to offset conduit!

Entrance Ells

- Designed for a straight pull in either direction
- Smooth surface
- Make it easy to pull heavy wires without damage to insulation
- Made of copper-free aluminum

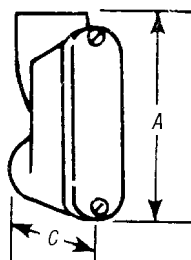

CAT. NO.	CONDUIT SIZE	DIMENSIONS (IN.)	
		A	C
1490	1/2"	3	1 19/32
1491	3/4"	3 3/8	1 1/8
1492	1"	4 1/4	2 23/64
1493	1 1/4"	5 11/64	2 11/16
1494	1 1/2"	6 1/4	2 1/8
1495	2"	6 3/4	3 1/16

UL File No. E-23018.

CSA File Nos. 2884 and 589

Adjustable design fits a wide range of flange sizes!

Adjustable Beam Clamps

- Includes bolts
- Steel construction



CAT. NO.	DESCRIPTION
700TB	Fits Flange 2 3/4"–7 3/8"
701	Fits Flange 7"–12"
703	Special Bolt and (3) Nuts

CSA File No. 2884.

Fits any flange, tapered or straight, up to 5/8" thick!

Conduit Supports

- For use with standard rigid conduit, EMT or IMC
- Broad hook holds conduit at any desired angle
- Malleable iron construction



CAT. NO.	SIZE
690TB	1/2"
691TB	3/4"
692TB	1"
693TB	1 1/4"

CSA File No. 2884